



P0400.ZP

Material

Steel (class 5.8), bright zinc-plated.


Technical notes

To DIN 464, all knurled screws are one-piece manufactured, contrary to

the official standard sheet, they all have a thread up to the head, as shown, but no recess at the thread end.

Order No.	d ₁	l ₁	d ₂	d ₃	h ₁	h ₂	l ₂
P0400.030-006-ZP	M 3	6	12	6	7,5	2,5	2
P0400.030-010-ZP	M 3	10	12	6	7,5	2,5	2
P0400.030-012-ZP	M 3	12	12	6	7,5	2,5	2
P0400.030-016-ZP	M 3	16	12	6	7,5	2,5	2
P0400.040-006-ZP	M 4	6	16	8	9,5	3,5	2
P0400.040-008-ZP	M 4	8	16	8	9,5	3,5	2
P0400.040-010-ZP	M 4	10	16	8	9,5	3,5	2
P0400.040-012-ZP	M 4	12	16	8	9,5	3,5	2
P0400.040-016-ZP	M 4	16	16	8	9,5	3,5	2
P0400.040-020-ZP	M 4	20	16	8	9,5	3,5	2
P0400.040-025-ZP	M 4	25	16	8	9,5	3,5	2
P0400.050-006-ZP	M 5	6	20	10	11,5	4,0	2
P0400.050-008-ZP	M 5	8	20	10	11,5	4,0	2
P0400.050-010-ZP	M 5	10	20	10	11,5	4,0	2
P0400.050-012-ZP	M 5	12	20	10	11,5	4,0	2
P0400.050-016-ZP	M 5	16	20	10	11,5	4,0	2
P0400.050-020-ZP	M 5	20	20	10	11,5	4,0	2
P0400.050-025-ZP	M 5	25	20	10	11,5	4,0	2
P0400.050-030-ZP	M 5	30	20	10	11,5	4,0	2
P0400.060-008-ZP	M 6	8	24	12	15,0	5,0	2
P0400.060-010-ZP	M 6	10	24	12	15,0	5,0	2
P0400.060-012-ZP	M 6	12	24	12	15,0	5,0	2
P0400.060-016-ZP	M 6	16	24	12	15,0	5,0	2
P0400.060-020-ZP	M 6	20	24	12	15,0	5,0	2
P0400.060-025-ZP	M 6	25	24	12	15,0	5,0	2
P0400.060-030-ZP	M 6	30	24	12	15,0	5,0	2
P0400.060-035-ZP	M 6	35	24	12	15,0	5,0	2
P0400.060-040-ZP	M 6	40	24	12	15,0	5,0	2
P0400.080-012-ZP	M 8	12	30	16	18,0	6,0	2
P0400.080-016-ZP	M 8	16	30	16	18,0	6,0	2

Order No.	d ₁	l ₁	d ₂	d ₃	h ₁	h ₂	l ₂
P0400.080-020-ZP	M 8	20	30	16	18,0	6,0	2
P0400.080-025-ZP	M 8	25	30	16	18,0	6,0	2
P0400.080-030-ZP	M 8	30	30	16	18,0	6,0	2
P0400.080-035-ZP	M 8	35	30	16	18,0	6,0	2
P0400.080-040-ZP	M 8	40	30	16	18,0	6,0	2
P0400.100-020-ZP	M10	20	36	20	23,0	8,0	2
P0400.100-025-ZP	M10	25	36	20	23,0	8,0	2
P0400.100-030-ZP	M10	30	36	20	23,0	8,0	2
P0400.100-035-ZP	M10	35	36	20	23,0	8,0	2
P0400.100-040-ZP	M10	40	36	20	23,0	8,0	2

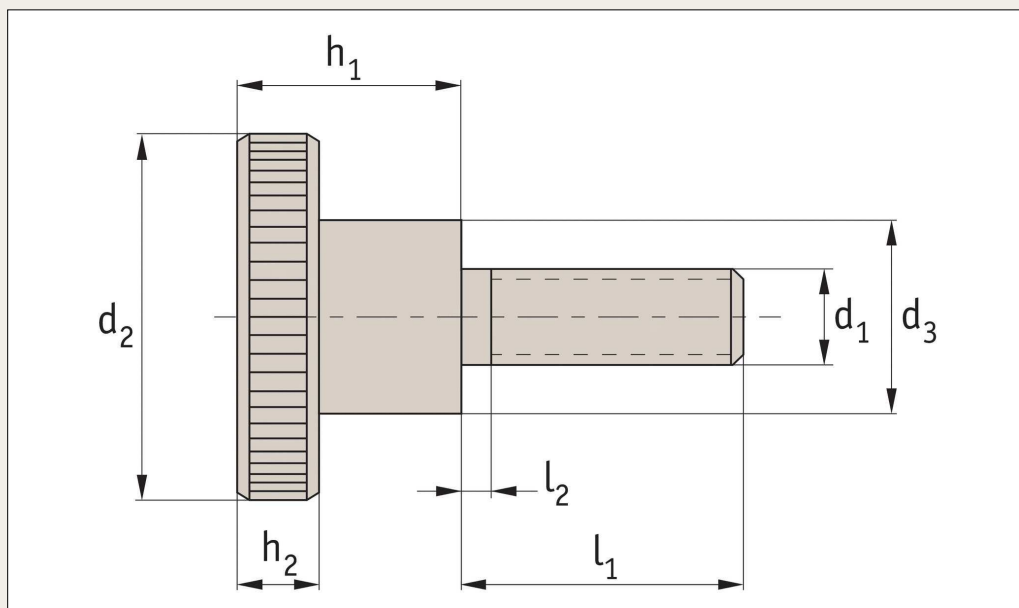

P0400.BL

Material

Steel (class 5.8), blackened.

Technical notes

To DIN 464, all knurled screws are one-piece manufactured, contrary to

the official standard sheet, they all have a thread up to the head, as shown, but no recess at the thread end.

Order No.	d ₁	l ₁	d ₂	d ₃	h ₁	h ₂	l ₂
P0400.030-006-BL	M 3	6	12	6	7,5	2,5	2
P0400.030-010-BL	M 3	10	12	6	7,5	2,5	2
P0400.030-012-BL	M 3	12	12	6	7,5	2,5	2
P0400.030-016-BL	M 3	16	12	6	7,5	2,5	2
P0400.040-006-BL	M 4	6	16	8	9,5	3,5	2
P0400.040-008-BL	M 4	8	16	8	9,5	3,5	2
P0400.040-010-BL	M 4	10	16	8	9,5	3,5	2
P0400.040-012-BL	M 4	12	16	8	9,5	3,5	2
P0400.040-016-BL	M 4	16	16	8	9,5	3,5	2
P0400.040-020-BL	M 4	20	16	8	9,5	3,5	2
P0400.040-025-BL	M 4	25	16	8	9,5	3,5	2
P0400.050-006-BL	M 5	6	20	10	11,5	4,0	2
P0400.050-008-BL	M 5	8	20	10	11,5	4,0	2
P0400.050-010-BL	M 5	10	20	10	11,5	4,0	2
P0400.050-012-BL	M 5	12	20	10	11,5	4,0	2
P0400.050-016-BL	M 5	16	20	10	11,5	4,0	2
P0400.050-020-BL	M 5	20	20	10	11,5	4,0	2
P0400.050-025-BL	M 5	25	20	10	11,5	4,0	2
P0400.050-030-BL	M 5	30	20	10	11,5	4,0	2
P0400.060-008-BL	M 6	8	24	12	15,0	5,0	2
P0400.060-010-BL	M 6	10	24	12	15,0	5,0	2
P0400.060-012-BL	M 6	12	24	12	15,0	5,0	2
P0400.060-016-BL	M 6	16	24	12	15,0	5,0	2
P0400.060-020-BL	M 6	20	24	12	15,0	5,0	2
P0400.060-025-BL	M 6	25	24	12	15,0	5,0	2
P0400.060-030-BL	M 6	30	24	12	15,0	5,0	2
P0400.060-035-BL	M 6	35	24	12	15,0	5,0	2
P0400.080-012-BL	M 8	12	30	16	18,0	6,0	2
P0400.080-016-BL	M 8	16	30	16	18,0	6,0	2
P0400.080-020-BL	M 8	20	30	16	18,0	6,0	2

Order No.	d ₁	l ₁	d ₂	d ₃	h ₁	h ₂	l ₂
P0400.080-025-BL	M 8	25	30	16	18,0	6,0	2
P0400.080-030-BL	M 8	30	30	16	18,0	6,0	2
P0400.080-035-BL	M 8	35	30	16	18,0	6,0	2
P0400.080-040-BL	M 8	40	30	16	18,0	6,0	2
P0400.100-020-BL	M10	20	36	20	23,0	8,0	2
P0400.100-025-BL	M10	25	36	20	23,0	8,0	2
P0400.100-030-BL	M10	30	36	20	23,0	8,0	2
P0400.100-035-BL	M10	35	36	20	23,0	8,0	2
P0400.100-040-BL	M10	40	36	20	23,0	8,0	2