




Clevis Pin

silver zinc plated

Clevis Joints & Clips

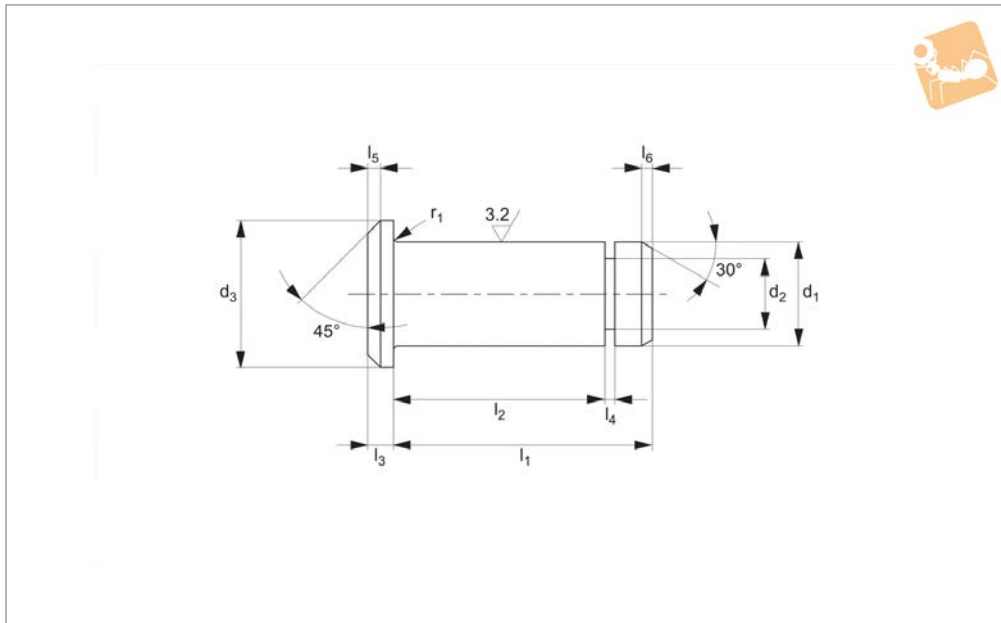

R3450

CLEVIS JOINTS & CLIPS

Material

Steel (9SMnPb28), silver zinc plated.

For safety fasteners, see R3440-R3445.

Technical Notes

Designed for use with clevis joints.

Tips

| Order No. | d ₁ tol. h11 | d ₂ tol. h11 | d ₃ tol. h12 | l ₁ | l ₂ +0.30 | l ₃ tol. js14 | l ₄ +0.10 | l ₅ | l ₆ | R | Weight g |
|--------------|----------------------------|----------------------------|----------------------------|----------------|-------------------------|-----------------------------|-------------------------|----------------|----------------|-----|-------------|
| R3450.004-ZP | 4 | 3.2 | 6 | 10.5 | 8.5 | 1.0 | 0.64 | 0.5 | 0.5 | 0.3 | 2 |
| R3450.005-ZP | 5 | 4.0 | 8 | 13.0 | 10.5 | 1.5 | 0.74 | 0.5 | 0.5 | 0.5 | 3 |
| R3450.006-ZP | 6 | 5.0 | 9 | 15.5 | 12.5 | 1.5 | 0.74 | 0.5 | 0.75 | 0.5 | 4 |
| R3450.008-ZP | 8 | 6.0 | 12 | 20.0 | 16.5 | 2.0 | 0.94 | 1.0 | 1.0 | 0.5 | 9 |
| R3450.010-ZP | 10 | 8.0 | 14 | 25.0 | 20.5 | 2.0 | 1.05 | 1.0 | 1.0 | 0.5 | 17 |
| R3450.012-ZP | 12 | 9.0 | 17 | 30.0 | 24.5 | 3.0 | 1.15 | 1.25 | 1.25 | 0.5 | 30 |
| R3450.014-ZP | 14 | 10.0 | 19 | 33.0 | 27.5 | 3.0 | 1.25 | 1.5 | 1.5 | 1.0 | 48 |
| R3450.016-ZP | 16 | 12.0 | 20 | 38.5 | 32.5 | 3.0 | 1.35 | 1.5 | 1.5 | 1.0 | 67 |
| R3450.020-ZP | 20 | 17.5 | 26 | 46.0 | 40.5 | 4.0 | 1.8 | 2.0 | 1.5 | 1.0 | 125 |
| R3450.025-ZP | 25 | 18.0 | 32 | 57.0 | 50.5 | 5.0 | 1.8 | 2.0 | 1.5 | 1.0 | 260 |
| R3450.004-A2 | 4 | 3.2 | 6 | 10.5 | 8.5 | 1.0 | 0.64 | 0.5 | 0.5 | 0.3 | 2 |
| R3450.005-A2 | 5 | 4.0 | 8 | 13.0 | 10.5 | 1.5 | 0.74 | 0.5 | 0.5 | 0.5 | 3 |
| R3450.006-A2 | 6 | 5.0 | 9 | 15.5 | 12.5 | 1.5 | 0.74 | 0.5 | 0.75 | 0.5 | 4 |
| R3450.008-A2 | 8 | 6.0 | 12 | 20.0 | 16.5 | 2.0 | 0.94 | 1.0 | 1.0 | 0.5 | 9 |
| R3450.010-A2 | 10 | 8.0 | 14 | 25.0 | 20.5 | 2.0 | 1.05 | 1.0 | 1.0 | 0.5 | 17 |
| R3450.012-A2 | 12 | 9.0 | 17 | 30.0 | 24.5 | 3.0 | 1.15 | 1.25 | 1.25 | 0.5 | 30 |
| R3450.014-A2 | 14 | 10.0 | 19 | 33.0 | 27.5 | 3.0 | 1.25 | 1.5 | 1.5 | 1.0 | 48 |
| R3450.016-A2 | 16 | 12.0 | 20 | 38.5 | 32.5 | 3.0 | 1.35 | 1.5 | 1.5 | 1.0 | 67 |
| R3450.020-A2 | 20 | 17.5 | 26 | 46.0 | 40.5 | 4.0 | 1.8 | 2.0 | 1.5 | 1.0 | 125 |
| R3450.025-A2 | 25 | 18.0 | 32 | 57.0 | 50.5 | 5.0 | 1.8 | 2.0 | 1.5 | 1.0 | 260 |